


B 53030
U-NUT® self-locking nuts

With metric fine thread of stainless steel

Stainless steel A2 | Cr(VI)-free | Metric standard thread

Further information: Material nuts: Stainless steel A2 | material insert: stainless steel

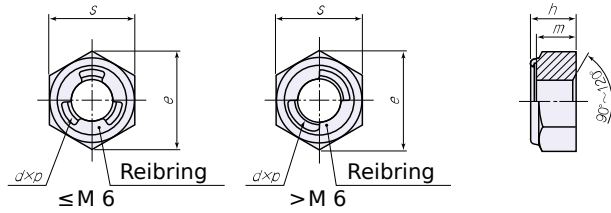

Diameter (d)	e nominal size	h		m nominal size	s		Pitch (P)	Sicherungsring
		nominal size	min. max.		nominal size	min. max.		
M4	8.1	3.8	3.5 4.1	3.0	7	6.80 7	0.70	dreifach je 60°
M5	9.2	4.6	4.3 4.9	3.9	8	7.80 8	0.80	dreifach je 60°
M6	11.5	5.1	4.8 5.4	4.2	10	9.80 10	1.00	dreifach je 60°
M8	15.0	7.3	6.9 7.7	6.1	13	12.75 13	1.25	zweifach je 90°
M10	19.6	8.3	7.9 8.7	7.1	17	16.75 17	1.50	zweifach je 90°
M12	21.9	10.5	10.1 10.9	9.0	19	18.65 19	1.75	zweifach je 90°
M16	27.7	14.5	14.0 15.0	13.0	24	23.65 24	2.00	zweifach je 90°

All technical data refer to the measure mm

