


**B 7505**

**Pressboard screws**

Countersunk head | cross-slot pozidriv

Stainless steel A2 | Cr(VI)-free | Wood thread

Further information: With partial thread from length 70 mm.

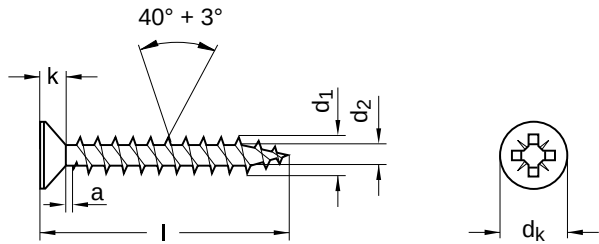

Diameter (d)	a		d <sub>1</sub>		d <sub>2</sub>		d <sub>k</sub>		k		Tool size
	max.	min.	min.	max.	min.	max.	min.	max.	min.	max.	
3	1.8	2.80	3.0	1.75	2.00	5.6	6	1.6	1.9	Z1	
3.5	2.0	3.30	3.5	2.00	2.25	6.6	7	1.8	2.1	Z2	
4	2.2	3.75	4.0	2.25	2.50	7.5	8	2.1	2.5	Z2	
4.5	2.4	4.25	4.5	2.45	2.70	8.5	9	2.3	2.7	Z2	
5	2.7	4.70	5.0	2.80	3.10	9.5	10	2.6	3.0	Z2	
6	3.4	5.70	6.0	3.50	3.80	11.5	12	3.1	3.6	Z3	

nominal size	Length (l)	
	min.	max.
12	11.1	12
16	15.1	16
20	18.9	20
25	23.9	25
30	28.9	30
35	33.7	35

nominal size	Length (l)	
	min.	max.
40	38.7	40
45	43.7	45

nominal size	Length (l)	
	min.	max.
50	48.7	50
60	58.5	60
70	68.5	70

Diameter (d)	Length (l)										
	12	16	20	25	30	35	40	45	50	60	70
3	●	●	●	●	●	●	●				
3.5	●	●	●	●	●	●	●				
4	●	●	●	●	●	●	●	●	●	●	
4.5			●	●	●	●	●	●	●	●	
5		●	●	●	●	●	●	●	●	●	●
6						●	●	●	●	●	

• Combinations available in the eShop | Other sizes on request

All technical data refer to the measure mm

