


**DIN 125 A** similar to ISO 7089/7090

# Washers

Form A: without chamfer

Brass | Cr(VI)-free

Further information: DIN standard has been withdrawn

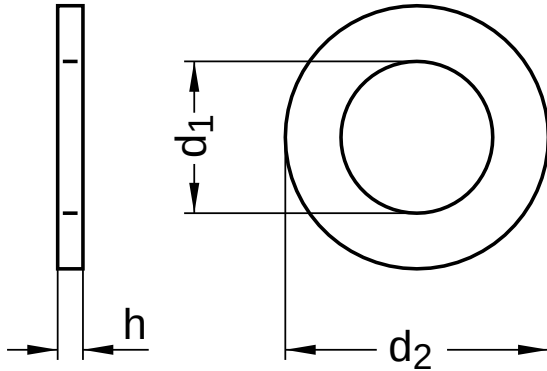

Diameter (d)	d <sub>1</sub>		d <sub>2</sub>		nominal size	h	
	min.	max.	min.	max.		min.	max.
1.7	1.7	1.84	3.70	4	0.3	0.25	0.35
2.2	2.2	2.34	4.70	5	0.3	0.25	0.35
2.7	2.7	2.84	5.70	6	0.5	0.45	0.55
3.2	3.2	3.38	6.64	7	0.5	0.45	0.55
3.7	3.7	3.88	7.64	8	0.5	0.45	0.55
4.3	4.3	4.48	8.64	9	0.8	0.70	0.90
5.3	5.3	5.48	9.64	10	1.0	0.90	1.10
6.4	6.4	6.62	11.57	12	1.6	1.40	1.80
7.4	7.4	7.62	13.57	14	1.6	1.40	1.80
8.4	8.4	8.62	15.57	16	1.6	1.40	1.80
10.5	10.5	10.77	19.48	20	2.0	1.80	2.20
13	13.0	13.27	23.48	24	2.5	2.30	2.70
15	15.0	15.27	27.48	28	2.5	2.30	2.70
17	17.0	17.27	29.48	30	3.0	2.70	3.30
19	19.0	19.33	33.38	34	3.0	2.70	3.30
21	21.0	21.33	36.38	37	3.0	2.70	3.30
23	23.0	23.33	38.38	39	3.0	2.70	3.30
25	25.0	25.33	43.38	44	4.0	3.70	4.30
28	28.0	28.33	49.38	50	4.0	3.70	4.30
31	31.0	31.39	55.26	56	4.0	3.70	4.30
34	34.0	34.62	58.80	60	5.0	4.40	5.60
37	37.0	37.62	64.80	66	5.0	4.40	5.60
40	40.0	40.62	70.80	72	6.0	5.40	6.60
43	43.0	43.62	76.80	78	7.0	6.00	8.00

All technical data refer to the measure mm

