


DIN 125 A similar to ISO 7089/7090

Washers

Form A: without chamfer

Steel 140 HV | hot-dip galvanised | Cr(VI)-free

Further information: DIN standard has been withdrawn

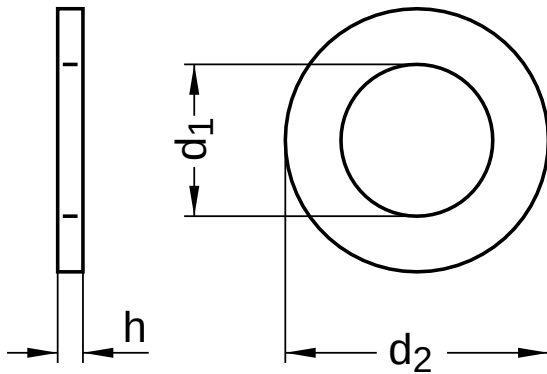

Diameter (d)	d ₁		d ₂		h		
	min.	max.	min.	max.	nominal size	min.	max.
6.4	6.4	6.62	11.57	12	1.6	1.4	1.8
8.4	8.4	8.62	15.57	16	1.6	1.4	1.8
10.5	10.5	10.77	19.48	20	2.0	1.8	2.2
13	13.0	13.27	23.48	24	2.5	2.3	2.7
15	15.0	15.27	27.48	28	2.5	2.3	2.7
17	17.0	17.27	29.48	30	3.0	2.7	3.3
19	19.0	19.33	33.38	34	3.0	2.7	3.3
21	21.0	21.33	36.38	37	3.0	2.7	3.3
23	23.0	23.33	38.38	39	3.0	2.7	3.3
25	25.0	25.33	43.38	44	4.0	3.7	4.3
28	28.0	28.33	49.38	50	4.0	3.7	4.3
31	31.0	31.39	55.26	56	4.0	3.7	4.3

All technical data refer to the measure mm

