


**DIN 127 B**  
**Spring washers**

Form A: even

Spring steel | hot-dip galvanised | Cr(VI)-free

Further information: Norm has been withdrawn without replacement

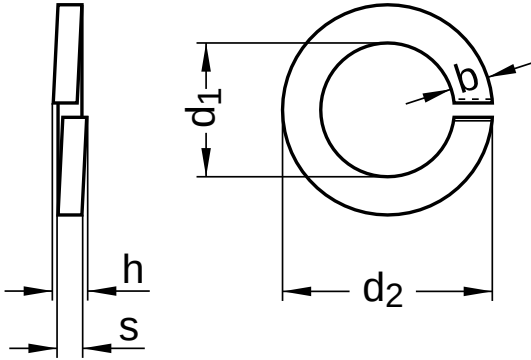

Diameter (d)	b		d <sub>1</sub>		d <sub>2</sub> max.	h		s			
	nominal size	min.	max.	min.		max.	min.	max.	nominal size	min.	max.
8	3.0	2.85	3.15	8.1	8.5	14.8	4.0	4.7	2.0	1.90	2.10
10	3.5	3.30	3.70	10.2	10.7	18.1	4.4	5.2	2.2	2.05	2.35
12	4.0	3.80	4.20	12.2	12.7	21.1	5.0	5.9	2.5	2.35	2.65
16	5.0	4.80	5.20	16.2	17.0	27.4	7.0	8.3	3.5	3.30	3.70
20	6.0	5.80	6.20	20.2	21.2	33.6	8.0	9.4	4.0	3.80	4.20
22	6.0	5.80	6.20	22.5	23.5	35.9	8.0	9.4	4.0	3.80	4.20
24	7.0	6.75	7.25	24.5	25.5	40.0	10.0	11.8	5.0	4.80	5.20
27	7.0	6.75	7.25	27.5	28.5	43.0	10.0	11.8	5.0	4.80	5.20
30	8.0	7.75	8.25	30.5	31.7	48.2	12.0	14.2	6.0	5.80	6.20
36	10.0	9.75	10.25	36.5	37.7	58.2	12.0	14.2	6.0	5.80	6.20
39	10.0	9.75	10.25	39.5	40.7	61.2	12.0	14.2	6.0	5.80	6.20
42	12.0	11.75	12.25	42.5	43.7	68.2	14.0	16.5	7.0	6.75	7.25
45	12.0	11.75	12.25	45.5	46.7	71.2	14.0	16.5	7.0	6.75	7.25
48	12.0	11.75	12.25	49.0	50.5	75.0	14.0	16.5	7.0	6.75	7.25
52	14.0	13.75	14.25	53.0	54.5	83.0	16.0	18.9	8.0	7.75	8.25

All technical data refer to the measure mm

