


DIN 440 R similar to ISO 7094

Washers

Form R: round hole

Steel | bright | Cr(VI)-free

Further information: DIN-standard has been withdrawn

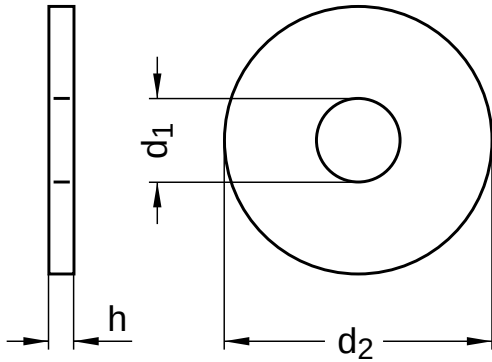

Diameter (d)	d ₁		d ₂		h		
	min.	max.	min.	max.	nominal size	min.	max.
5.5	5.5	5.80	16.9	18	2	1.7	2.3
6.6	6.6	6.96	20.7	22	2	1.7	2.3
9	9.0	9.36	26.7	28	3	2.4	3.6
11	11.0	11.43	32.4	34	3	2.4	3.6
13.5	13.5	13.93	42.4	44	4	3.4	4.6
17.5	17.5	18.20	54.1	56	5	4.0	6.0
22	22.0	22.84	70.1	72	6	5.0	7.0
24	24.0	24.84	78.1	80	6	5.0	7.0
26	26.0	26.84	82.8	85	6	5.0	7.0
30	30.0	30.84	95.8	98	6	5.0	7.0

All technical data refer to the measure mm

