


DIN 525

Weld stud ends

With hexagon nut

Steel | bright | Cr(VI)-free | Metric thread

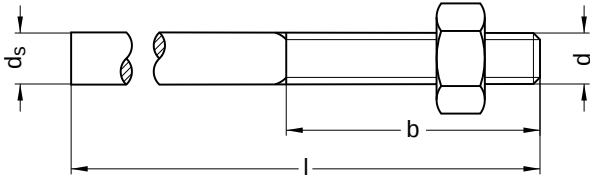

Diameter (d)	b nominal size	d _s max.	Pitch (P)
M6	35	6	1.00
M8	40	8	1.25
M10	45	10	1.50
M12	55	12	1.75
M16	65	16	2.00
M24	85	24	3.00
M30	105	30	3.50
M36	125	36	4.00

nominal size	Length (l)	
	min.	max.
130	128.0	132.0
140	138.0	142.0
150	148.0	152.0
170	168.0	172.0
190	187.7	192.3
230	227.7	232.3

nominal size	Length (l)	
	min.	max.
270	267.4	272.6
310	307.4	312.6

All technical data refer to the measure mm



DIN 525

Weld stud ends

With hexagon nut

Steel | bright | Cr(VI)-free | Metric thread

Diameter (d)	Length (l)							
	130	140	150	170	190	230	270	310
M6	●							
M8		●						
M10			●					
M12				●				
M16					●			
M24						●		
M30							●	
M36								●

• Combinations available in the eShop | Other sizes on request

All technical data refer to the measure mm

