


DIN 6885

Parallel keys

Form A: round-ended without drilling

Steel | bright | Cr(VI)-free

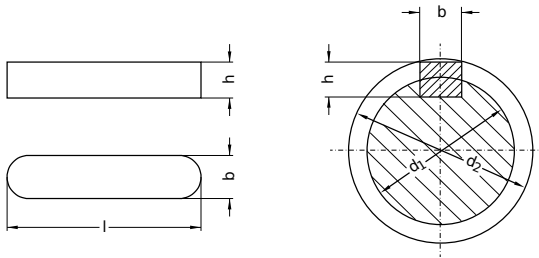

Diameter (d)	b nominal size	d ₁		d ₂ min.	h nominal size
		min.	max.		
2 x 2	2	6	8	2.5	2
3 x 3	3	8	10	3.5	3
4 x 4	4	10	12	4.0	4
5 x 5	5	12	17	5.0	5
6 x 6	6	17	22	6.0	6
8 x 7	8	22	30	8.0	7
10 x 8	10	30	38	8.0	8
12 x 8	12	38	44	8.0	8
14 x 9	14	44	50	9.0	9
16 x 10	16	50	58	11.0	10
18 x 11	18	58	65	11.0	11
20 x 12	20	65	75	12.0	12
22 x 14	22	75	85	14.0	14
25 x 14	25	85	95	14.0	14
28 x 16	28	95	110	16.0	16
32 x 18	32	110	130	18.0	18
36 x 20	36	130	150	21.0	20
40 x 22	40	150	170	23.0	22

All technical data refer to the measure mm



DIN 6885

Parallel keys

Form A: round-ended without drilling

Steel | bright | Cr(VI)-free

nominal size	Length (l)	
	min.	max.
8	7.80	8.20
10	9.80	10.20
12	11.80	12.20
14	13.80	14.20
16	15.80	16.20
18	17.80	18.20
20	19.80	20.20
22	21.80	22.20
25	24.80	25.20
28	27.80	28.20
30	29.75	30.25
32	31.70	32.30

nominal size	Length (l)	
	min.	max.
36	35.70	36.30
40	39.70	40.30
45	44.70	45.30
50	49.70	50.30
56	55.70	56.30
60	59.70	60.30
63	62.70	63.30
70	69.70	70.30
80	79.70	80.30
90	89.50	90.50
100	99.50	100.50
110	109.50	110.50

nominal size	Length (l)	
	min.	max.
120	119.50	120.50
125	124.50	125.50
130	-	-
140	139.50	140.50
160	159.50	160.50
180	179.50	180.50
200	199.50	200.50
220	219.50	220.50
250	249.50	250.50
280	279.50	280.50
350	349.50	350.50

All technical data refer to the measure mm



DIN 6885

Parallel keys

Form A: round-ended without drilling

Steel | bright | Cr(VI)-free

Diameter (d)	Length (l)																
	8	10	12	14	16	18	20	22	25	28	30	32	36	40	45	50	56
2 x 2	●	●															
3 x 3	●	●	●	●	●	●	●	●	●	●							
4 x 4	●	●	●	●	●	●	●	●	●	●	●	●		●	●		
5 x 5		●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
6 x 6				●	●	●	●	●	●	●	●	●	●	●	●	●	●
8 x 7						●	●	●	●	●	●	●	●	●	●	●	●
10 x 8								●	●	●	●	●	●	●	●	●	●
12 x 8										●			●	●	●	●	●
14 x 9													●	●	●	●	●
16 x 10															●	●	●
18 x 11															●	●	●
20 x 12																	
22 x 14																	
25 x 14																	
28 x 16																	
32 x 18																	
36 x 20																	
40 x 22																	

Diameter (d)	Length (l)																	
	60	63	70	80	90	100	110	120	125	130	140	160	180	200	220	250	280	350
2 x 2																		
3 x 3																		
4 x 4																		
5 x 5																		
6 x 6		●	●															
8 x 7	●	●	●	●	●	●												
10 x 8	●	●	●	●	●	●	●											
12 x 8	●	●	●	●	●	●	●	●			●							
14 x 9	●	●	●	●	●	●	●				●							
16 x 10	●	●	●	●	●	●	●	●				●						
18 x 11		●	●	●	●	●	●	●					●	●				
20 x 12		●	●	●	●	●	●	●	●			●	●	●				
22 x 14			●			●					●				●	●		
25 x 14						●	●		●		●	●	●	●			●	
28 x 16						●	●			●		●	●		●		●	
32 x 18						●					●	●	●			●		
36 x 20																●		
40 x 22														●		●		●

• Combinations available in the eShop | Other sizes on request

All technical data refer to the measure mm

