


DIN 835
Studs

Threaded end $\approx 2 d$

Steel 5.8 | bright | Cr(VI)-free | Metric thread

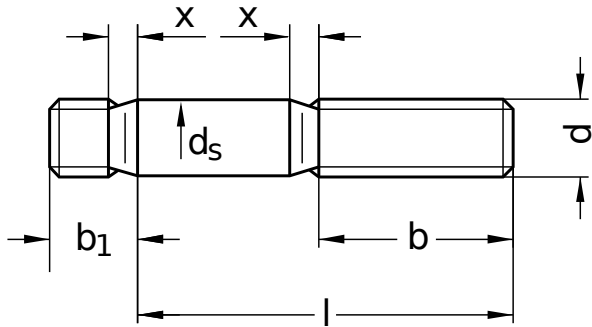

Diameter (d)	b			b ₁ nominal size	d _s		Pitch (P)	x
	l up to 125	l up to 200	l longer than 200		min.	max.		
M6	18	24	–	12	5.82	6	1.00	2.5
M8	22	28	–	16	7.78	8	1.25	3.2
M10	26	32	45	20	9.78	10	1.50	3.8
M12	30	36	49	24	11.73	12	1.75	4.3
M16	38	44	57	32	15.73	16	2.00	5.0

nominal size	Length (l)	
	min.	max.
25	24.58	25.42
28	27.58	28.42
30	29.58	30.42
35	34.50	35.50
40	39.50	40.50
45	44.50	45.50

nominal size	Length (l)	
	min.	max.
50	49.50	50.50
55	54.40	55.60
60	59.40	60.60
65	64.40	65.60
70	69.40	70.60
75	74.40	75.60

nominal size	Length (l)	
	min.	max.
80	79.40	80.60
85	84.30	85.70
90	89.30	90.70
95	94.30	95.70
100	99.30	100.70

Diameter (d)	Length (l)																
	25	28	30	35	40	45	50	55	60	65	70	75	80	85	90	95	100
M6	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
M8			●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
M10				●	●	●	●	●	●	●	●	●	●	●	●	●	●
M12					●	●	●	●	●	●	●	●	●	●	●	●	●
M16	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●

• Combinations available in the eShop | Other sizes on request

All technical data refer to the measure mm

