


DIN 936

Hexagon nuts

Low form | external hex

Steel 17 H | bright | Cr(VI)-free | Metric fine thread

Further information: Norm has been withdrawn without replacement

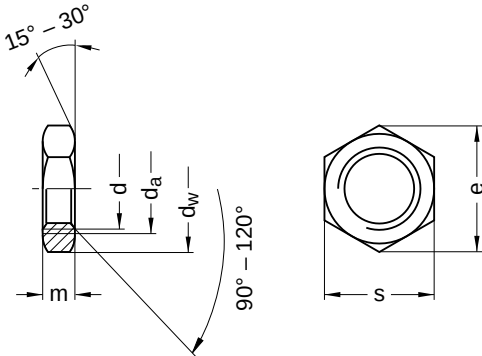

Diameter (d)	d _a		d _w	e	m		s		Pitch (P)	Tool size
	min.	max.			min.	max.	min.	max.		
M8 x 1	8	8.75	11.3	14.38	4.70	5	12.73	13	1.0	SW 13
M10 x 1	10	10.80	15.3	18.90	5.70	6	16.73	17	1.0	SW 17
M12 x 1.5	12	13.00	17.2	21.10	6.64	7	18.67	19	1.5	SW 19
M14 x 1.5	14	15.10	20.2	24.49	7.42	8	21.67	22	1.5	SW 22
M16 x 1.5	16	17.30	22.2	26.75	7.42	8	23.67	24	1.5	SW 24
M18 x 1.5	18	19.50	25.3	29.56	8.42	9	26.16	27	1.5	SW 27
M20 x 1.5	20	21.60	28.2	32.95	8.10	9	29.16	30	1.5	SW 30
M20 x 2	20	21.60	28.2	32.95	8.10	9	29.16	30	2.0	SW 30
M22 x 1.5	22	23.70	29.5	35.03	9.10	10	31.00	32	1.5	SW 32
M22 x 2	22	23.70	29.5	35.03	9.10	10	31.00	32	2.0	SW 32
M24 x 1.5	24	25.90	33.2	39.55	9.10	10	35.00	36	1.5	SW 36
M24 x 2	24	25.90	33.2	39.55	9.10	10	35.00	36	2.0	SW 36
M27 x 1.5	27	29.10	38.0	45.20	10.90	12	40.00	41	1.5	SW 41
M27 x 2	27	29.10	38.0	45.20	10.90	12	40.00	41	2.0	SW 41
M30 x 1.5	30	32.40	42.7	50.85	10.90	12	45.00	46	1.5	SW 46
M30 x 2	30	32.40	42.7	50.85	10.90	12	45.00	46	2.0	SW 46

All technical data refer to the measure mm

