

E 1412


EJOT®-PT screws

Linsenkopf | Kreuzschlitz Z (Pozidriv)

Stainless steel A2 | Cr(VI)-free | Self-tapping thread

Further information: For further information and CAD-files please follow the link to the EJOT-homepage:

<http://www.ejot.com/industry>

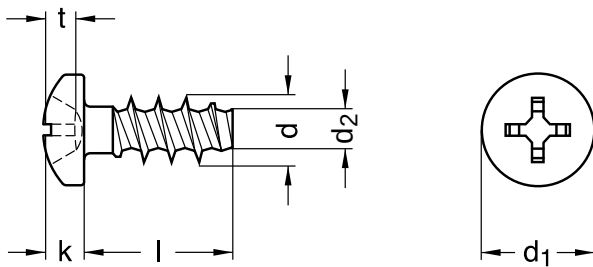

Diameter (d)	d ₁ nominal size	d ₂ nominal size	k nominal size	Pitch (P)	t	
					max.	min.
2.2	3.9	1.25	1.5	0.98	1.20	0.74
3	5.3	1.66	2.0	1.34	1.65	1.19
4	7	2.17	2.7	1.79	2.14	1.51

Length (l) nominal size
5
7
8
10
18
20

Diameter (d)	Length (l)					
	5	7	8	10	18	20
2.2		●				
3	●		●	●		●
4					●	●

• Combinations available in the eShop | Other sizes on request

All technical data refer to the measure mm

