


**ISO 8750**  
**Spiral spring pins**

Medium duty

Spring steel | bright | Cr(VI)-free

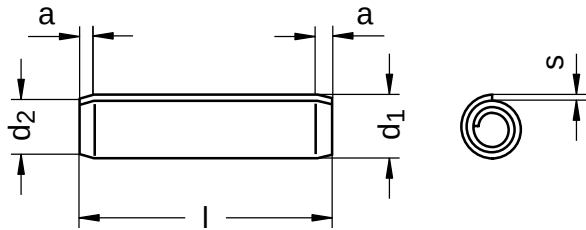

Diameter (d)	a	d <sub>1</sub>			d <sub>2</sub> max.	s nominal size
		nominal size	min.	max.		
2	0.7	2	2.13	2.25	1.90	1.9
3	0.9	3	3.15	3.30	2.90	4.2
4	1.1	4	4.20	4.40	3.90	7.6
5	1.3	5	5.25	5.50	4.85	11.5
6	1.5	6	6.25	6.50	5.85	16.8
8	2.0	8	8.30	8.63	7.80	30.0
10	2.5	10	10.35	10.80	9.75	48.0
12	3.0	12	12.40	12.85	11.70	67.0
14	3.5	14	14.45	14.95	13.60	-
16	4.0	16	16.45	17.00	15.60	-

nominal size	Length (l)	
	min.	max.
4	3.75	4.25
5	4.75	5.25
6	5.75	6.25
8	7.75	8.25
10	9.75	10.25
12	11.50	12.50
14	13.50	14.50
16	15.50	16.50
18	17.50	18.50
20	19.50	20.50
22	21.50	22.50
24	23.50	24.50

nominal size	Length (l)	
	min.	max.
26	25.50	26.50
28	27.50	28.50
30	29.50	30.50
32	31.50	32.50
36	35.50	36.50
40	39.50	40.50
45	44.50	45.50
50	49.50	50.50
55	54.25	55.75
60	59.25	60.75
65	64.25	65.75
70	69.25	70.75

nominal size	Length (l)	
	min.	max.
75	74.25	75.75
80	79.25	80.75
85	84.25	85.75
90	89.25	90.75
95	94.25	95.75
100	99.25	100.75
120	119.25	120.75
140	139.25	140.75
160	159.25	160.75
180	179.25	180.75

All technical data refer to the measure mm



**ISO 8750**  
**Spiral spring pins**  
 Medium duty

Spring steel | bright | Cr(VI)-free

Diameter (d)	Length (l)																																							
	4	5	6	8	10	12	14	16	18	20	22	24	26	28	30	32	36	40	45	50	55	60	65	70	75	80	85	90	95	100	120	140	160	180						
2	●	●	●	●	●	●	●	●	●	●																														
3			●	●	●	●	●	●	●	●	●	●	●	●	●	●																								
4				●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
5					●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
6						●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
8								●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
10											●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
12																●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
14																		●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
16																				●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●

• Combinations available in the eShop | Other sizes on request

All technical data refer to the measure mm

