


ISO 8752 similar to DIN 1481

Spring pins

Heavy duty

Stainless steel 1.4310 | Cr(VI)-free

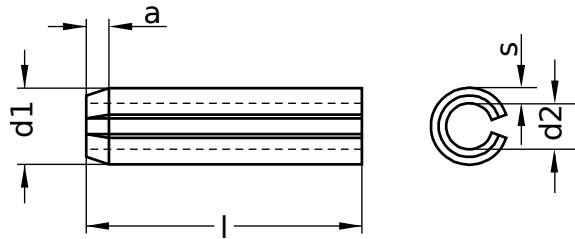

Diameter (d)	a		d ₁			d ₂		s
	min.	max.	nominal size	min.	max.	nominal size	nominal size	
1	0.15	0.35	1	1.2	1.3	0.8	0.20	
1.5	0.25	0.45	1.5	1.7	1.8	1.1	0.30	
2	0.35	0.55	2	2.3	2.4	1.5	0.40	
2.5	0.40	0.60	2.5	2.8	2.9	1.8	0.50	
3	0.50	0.70	3	3.3	3.5	2.1	0.60	
3.5	0.60	0.80	3.5	3.8	4.0	2.3	0.75	
4	0.65	0.85	4	4.4	4.6	2.8	0.80	
4.5	0.80	1.00	4.5	4.9	5.1	2.9	1.00	
5	0.90	1.10	5	5.4	5.6	3.4	1.00	
6	1.20	1.40	6	6.4	6.7	4	1.20	
8	1.60	2.00	8	8.5	8.8	5.5	1.50	
10	2.00	2.40	10	10.5	10.8	6.5	2.00	

nominal size	Length (l)	
	min.	max.
4	3.75	4.25
5	4.75	5.25
6	5.75	6.25
8	7.75	8.25
10	9.75	10.25
12	11.50	12.50
14	13.50	14.50
16	15.50	16.50
18	17.50	18.50
20	19.50	20.50

nominal size	Length (l)	
	min.	max.
22	21.50	22.50
24	23.50	24.50
26	25.50	26.50
28	27.50	28.50
30	29.50	30.50
32	31.50	32.50
36	35.50	36.50
40	39.50	40.50
45	44.50	45.50
50	49.50	50.50

nominal size	Length (l)	
	min.	max.
55	54.25	55.75
60	59.25	60.75
65	64.25	65.75
70	69.25	70.75
75	74.25	75.75
80	79.25	80.75
85	84.25	85.75
90	89.25	90.75
95	94.25	95.75
100	99.25	100.75

All technical data refer to the measure mm



ISO 8752 similar to DIN 1481

Spring pins

Heavy duty

Stainless steel 1.4310 | Cr(VI)-free

Diameter (d)	Length (l)																														
	4	5	6	8	10	12	14	16	18	20	22	24	26	28	30	32	36	40	45	50	55	60	65	70	75	80	85	90	95	100	
1	●	●	●	●		●	●	●	●	●																					
1.5	●	●	●	●	●	●	●	●	●	●																					
2	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●																
2.5	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
3	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
3.5	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
4	●	●		●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
4.5			●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
5				●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
6						●	●		●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
8					●	●		●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
10					●	●		●		●	●	●	●		●		●	●	●	●	●	●	●	●	●	●	●	●	●	●	

• Combinations available in the eShop | Other sizes on request

All technical data refer to the measure mm

