

RIVKLE® Force controller

RIVKLE® force controller FC340:

- To optimise the adjustment of force-controlled mechanical installation tools
- For RIVKLE® NEO P107, NEO B107, NEO B109, B2007, P1007, P2007, P3007, P2007 PN and P3007 PN
- Force measuring range: 3 kN–40 kN
- Tooling not included (to be ordered separately according to the size)

Technical information can be found on the last page.




Article number


28252214000

All technical data refer to the measure mm




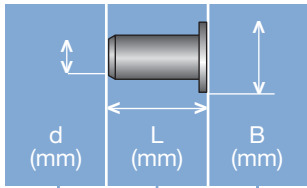


Head diameter
Overall length
Thread size

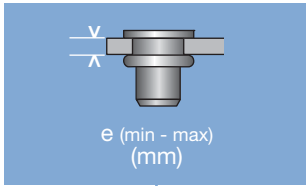

Grip range
Defines the range of total thickness of the customers part (even if it consists of more than one layer)

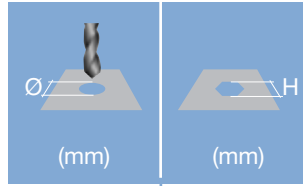

Hole geometry
If round → diameter
If hexagonal → width across flats

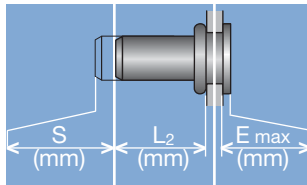


Head projection after setting
Variable according to the application (setting load, material substrate, etc.)


Blind side projection after installation
Defines the clearance needed on the blind side (cannot be used for quality control)

Setting stroke
Difference of total length before and after installation

 RIVKLE® Nut



RIVKLE® Stud

 

- RIVKLE®
- Mandrel*
- Customers part
- Anvil*
- Counter nut
- Setting tool

in accordance to chosen RIVKLE®

All technical data refer to the measure mm

