

# RIVQUICK® Varibolt multigrip blind rivets

## Countersunk head

Note: stainless steel A2 body and stainless steel A2 mandrel

Technical information can be found on the last page.




Diameter (d)	Article number	d <sub>1</sub> nominal size	d <sub>2</sub> nominal size	Drilling diameter d nominal size	e	
					min.	max.
6.4	22083264160	6.4	10.2	6.6	3.2	12.0
	22383264160		10	6.6 - 7.0		12.1

Diameter (d)	Length (l) nominal size	Head thickness	Shear force (N)	Tensile force (N)
6.4	16	2.4	10602	9405
	30	1.9	13000	9500

All technical data refer to the measure mm



## Symbol list

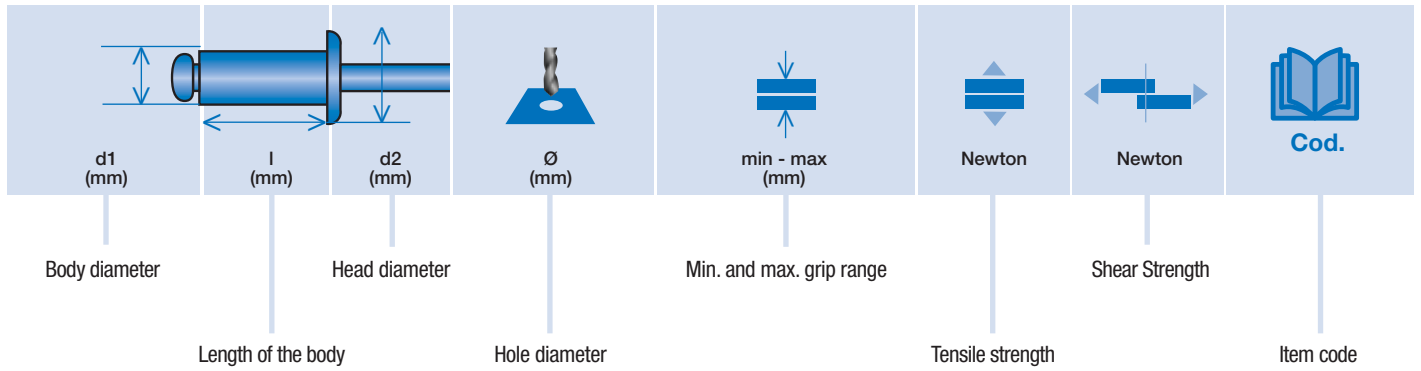

All technical data refer to the measure mm

