

# RIVQUICK® Varigrip multigrip blind rivets

## Dome head

Note: steel body and steel mandrel

Technical information can be found on the last page.




Diameter (d)	Article number	d <sub>1</sub>	d <sub>2</sub>	Drilling diameter d nominal size	e	
		nominal size	nominal size		min.	max.
3.2	22022132120	3.2	7.6	3.3 - 3.4	1.0	7.0
4	22022140130	4	8.4	4.1 - 4.2	2.0	8.0
4.8	22022148110	4.8	10.1	4.9 - 5.0	1.5	6.3

Diameter (d)	Length (l) nominal size	Head thickness	Shear force (N)	Tensile force (N)
3.2	12	1.1	1000	1400
4	13	1.5	1500	2000
4.8	11	1.6	2700	2900

All technical data refer to the measure mm



## Symbol list

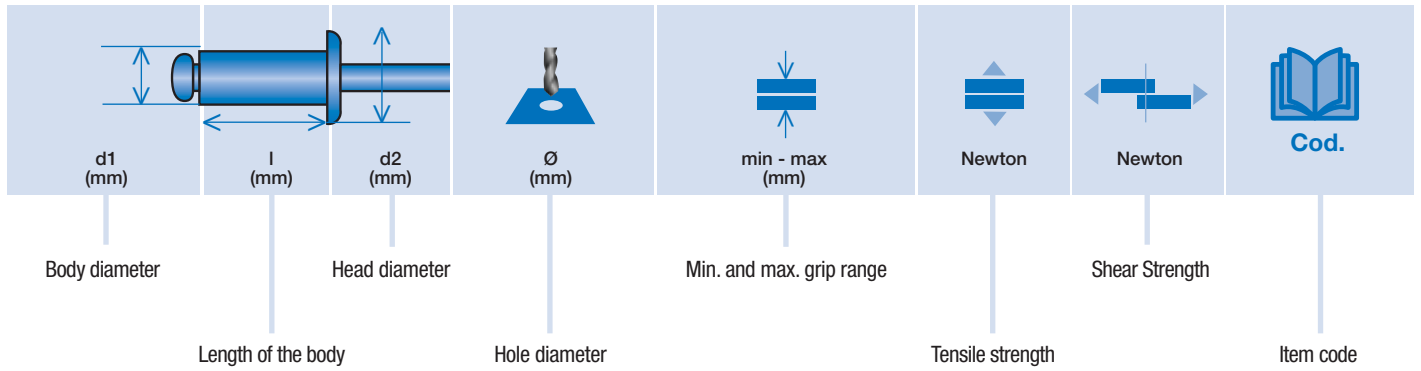

All technical data refer to the measure mm