


SNAPLOC® Ball studs

Metrical external thread

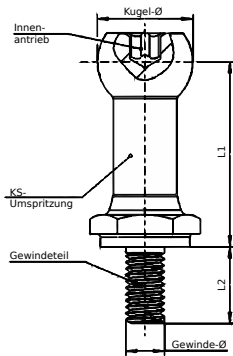

| Article number | Outer dimension | Depth (L1) | Colour | Thread dimensions | Thread length (L2) | Ball diameter (D) |
|----------------|-----------------|------------|--------|-------------------|--------------------|-------------------|
| 40300070006 | SW 10 | 11.9 | black | M6 | 9 | 7 |
| 40300100049 | SW 12 | 35.1 | black | M6 | 12 | 10 |
| 40300150005 | SW 15 | 21.0 | black | M6 | 12 | 15 |
| 40300150007 | SW 15 | 12.0 | black | M6 | 8 | 15 |
| 40311003905 | SW 13 | 16.0 | black | M6 | 12 | 10 |
| 40341503901 | SW 15 | 29.0 | black | M6 | 12 | 15 |
| 40390010602 | SW 13 | 51.0 | black | M6 | 8 | 10 |
| 40390030604 | SW 15 | 61.0 | black | M6 | 12 | 15 |
| 40390050602 | SW 15 | 18.0 | black | M6 | 12 | 15 |
| 40390050605 | SW 15 | 32.0 | black | M6 | 12 | 15 |
| 40390060601 | SW 13 | 28.0 | black | M6 | 12 | 10 |
| 40390070604 | SW 10 | 9.9 | black | M6 | 9 | 8 |
| 40390070605 | SW 13 | 19.4 | black | M6 | 8 | 10 |
| 40390080016 | SW 13 | 18.0 | black | M6 | 14 | 8 |
| 40390080041 | SW 13 | 30.8 | black | M6 | 16 | 8 |
| 40390080045 | SW 17 | 26.3 | black | M6 | 8 | 8 |
| 40390080047 | SW 10 | 40.0 | black | M6 | 15 | 8 |
| 40390100057 | SW 13 | 34.0 | black | M6 | 10 | 10 |
| 40390150018 | - | 24.0 | grey | M6 | 12 | 15 |
| 40390150602 | SW 10 | 11.9 | black | M6 | 10 | 7 |
| 40390170603 | SW 12 | 43.5 | black | M6 | 12 | 10 |

All technical data refer to the measure mm

