


# SNAPLOC® Coupling

With Multiuptake

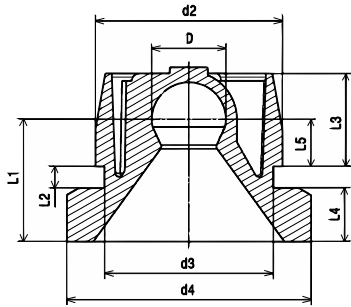

Article number	d <sub>2</sub> nominal size	Depth (L <sub>1</sub> )	Colour	Ball diameter (D)	d <sub>3</sub> nominal size	d <sub>4</sub>	Hardness	L <sub>3</sub>	L <sub>4</sub>	L <sub>5</sub>	Material thickness (L <sub>2</sub> )
40490100034	24.5	9	black	10	22.1	–	70 Shore A	12.00	–	6	2 - 3
40490100035	24.5	9	black	10	22.1	–	70 Shore A	12.00	–	6	2 - 3
40490100036	24.5	16	black	10	22.1	32	70 Shore A	12.15	6.85	6.15	3
40490100037	24.5	16	black	10	22.1	32	70 Shore A	12.15	6.85	6.15	3

All technical data refer to the measure mm

